

Casters with Mounting Plates / Leveling Mounts

Mounting Plate



Leveling Mount Unit

Part Number	Type	No.	Allowable Load kN(kgf)	Mass kg	Component				Unit Price		Volume Discount Rate
					Plate	Leveling Mount	Screw	Nut	1-8 pc(s).	9-20	
HAJPS	5	4.9(500)	0.45	HAJP5	NFJN12-100	CBM5-10	4	HNTT5-5	4		
	6		0.46	HAJP6		CBM6-12	4	HNTT6-6	4		
	8*			HAJP8		CBM8-20		HNTT8-8			
	5050	16.6(1700)	1.15	HAJPC5050	FJFN16-150	CBM6-15	8	HNTT6-6	8		
	6060		1.6	HAJPC6060							
	8080	39.2(4000)	2.5	HAJPC8080	FJFN20-150	CBM8-25		HNTT8-8			
9090		2.9	HAJPC9090								

8* is used in common with 8-45. Washers are included with HAJPS8080 only.
No. 6060, 8080 and 9090 are applicable to HFS6-6060, HFS8-8080 and HFS8-9090.

Plate with Caster (Caster with Stopper)

Part Number	Type	No.	Allowable Load kN(kgf)	Mass kg	Component				Unit Price		Volume Discount Rate
					Plate	Caster	Screw	Nut	1-8 pc(s).	9-20	
HCHPS	5	0.9(100)	0.69	HAJP5	HCHAS12-100	CBM5-10	4	HNTT5-5	4		
	6	1.4(150)	0.7	HAJP6	HCHAS12-150	CBM6-12		HNTT6-6			
	8*	1.7(170)	1.8	HAJP8	HCHAS16-170	CBM8-20		HNTT8-8			

8* is used in common with 8-45.
No. 5 and 6 apply to extrusions with 6-slot width 20 Square Type and 8-slot width 30 Square Types. No. 8 apply to extrusions 10-slot width 40 and 45 Square Type.

Leveling Mount + Plate with Caster

Part Number	Type	No.	Caster Allowable Load kN(kgf)	Leveling Mount Allowable Load kN(kgf)	Mass kg	Component						Unit Price		Volume Discount Rate		
						Plate	Leveling Mount	Caster	Extrusion Mounting	Nut	Quantity	1-8 pc(s).	9-20			
HAJCHP	5	0.9(100)	4.9(500)	0.86	HAJPC5	NFJN12-100	HCHA12-100	-	-	CBM5-10	4	HNTT5-5	4			
	2525				HAJPC2525											
	54040	16.6(1700)	1.62	HAJPC54040	NFJN16-150	CHJF50S	CBM6-10	4	CBM5-15	8						
	6	1.4(150)	4.9(500)	0.9	HAJPC6	NFJN12-100	HCHA12-150	-	-	CBM6-12	4	HNTT6-6	4			
	8*				HAJPC8					CBM8-20		HNTT8-8				
	5050	1.7(170)	16.6(1700)	2.2	HAJPC5050	FJFN16-150	CHJF50S			CBM6-15	8	HNTT6-6	8			
	6060	1.4(150)		1.9	HAJPC6060											
	8080	2.9(300)	39.2(4000)	3.4	HAJPC8080	FJFN20-150	CSHN-S75-H	CBM8-12		CBM8-25		HNTT8-8				
	9090			3.9	HAJPC9090											

8* is used in common with 8-45. Washers are included with HAJCH8080 only.

Ordering Example
Part Number
HAJCHP6060

Days to Ship
Configure Online






Example

Mounting Example
- Mounting of Leveling Mount

- Mounting of Plate with Caster

- Mounting of Leveling Mount + Plate with Caster

- Mounting of HAJPD (Next Page)

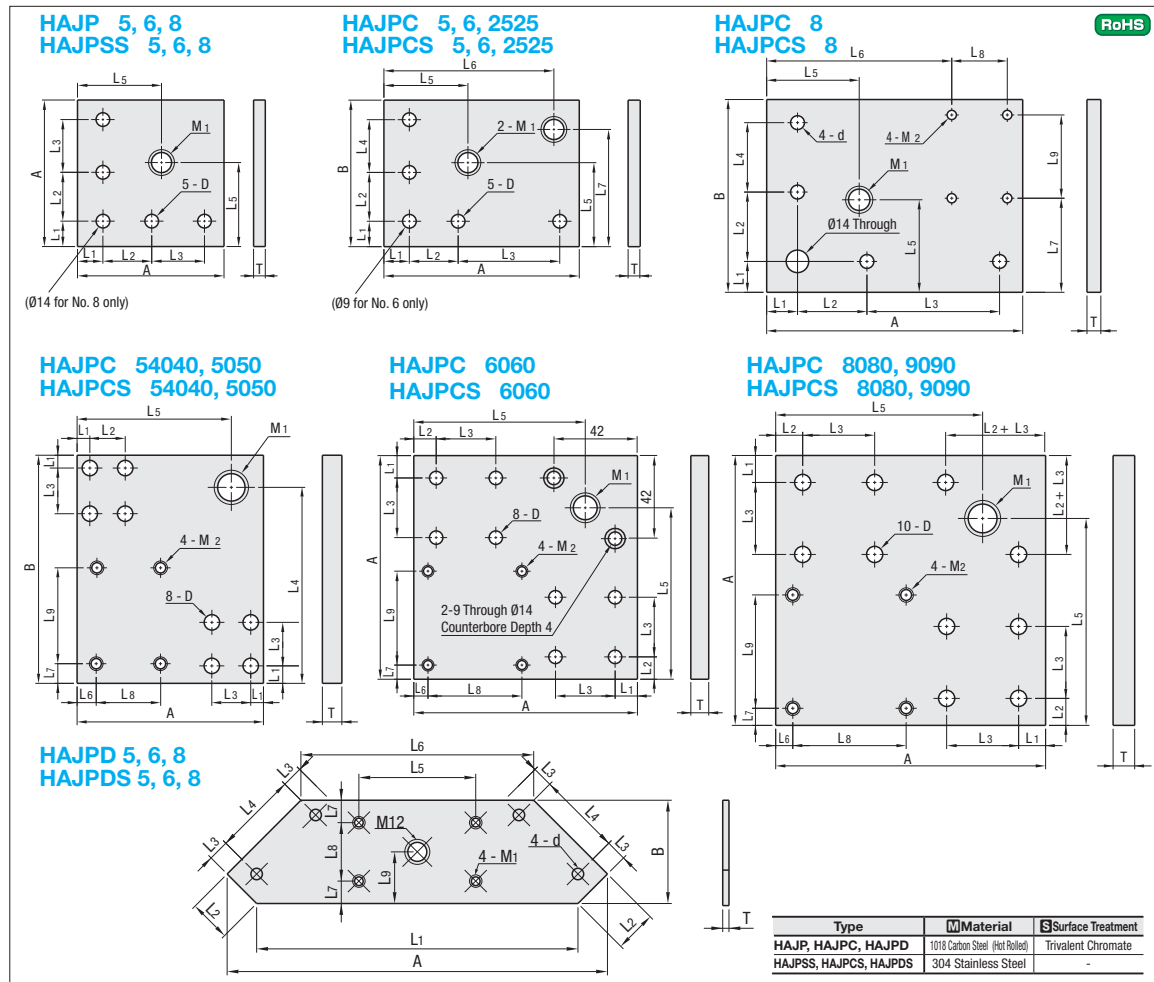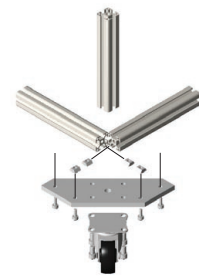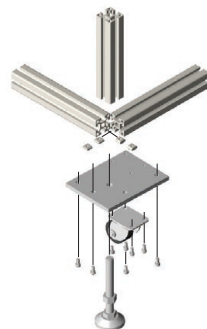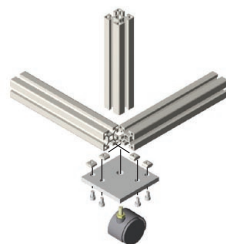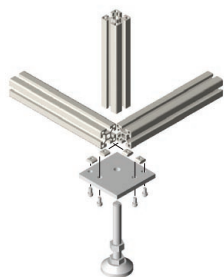

Type	Material	Surface Treatment
HAJP, HAJPC, HAJPD	1018 Carbon Steel (Hot Rolled)	Trivalent Chromate
HAJPSS, HAJPCS, HAJPDS	304 Stainless Steel	-

Part Number	Type	No.	A	B	T	M1	M2	D	L1	L2	L3	L4	L5	L6	L7	L8	L9	Mass kg	HAJP, HAJPC, HAJPD				HAJPSS, HAJPCS, HAJPDS			
																			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
HAJP HAJPSS	5	75	-	6	12	-	-	5.5	8	30	27	-	43	-	-	-	-	0.24								
	6	100	-	9	16	-	-	7	13	25	31	-	60	-	-	-	-	0.65								
	8*	100	9	16	-	-	-	9	20	45	25	-	60	-	-	-	-	0.65								
HAJPC HAJPCS	5	135	75	6	12	-	-	5.5	8	30	87	27	43	122	60	-	-	0.45								
	2525							10.5																		
	54040	100	125	9	16	6	-	8	20	20	107	82	11	10	36	54	0.82									
	6	135	75	6	12	-	-	7	13	25	87	31	43	122	60	-	-	0.44								
	8*	166	125	9	16	6	-	9	20	45	86	45	60	120	61	-	-	1.03								
	5050	150	-	-	-	-	-	7	10	60	20	65	106	10	10	36	54	1.03								
	6060	125	-	-	-	-	-	12	12	30	-	98	17	8	-	-	-	2								
8080	150	-	-	-	-	-	9	15	15	40	-	115	9.5	9.5	63	63	2									
9090	165	-	-	-	-	-	9	15	15	45	-	130	14	14	42	42	2.5									
HAJPD HAJPDS	5	184	50	6	6	-	-	5.5	154	20	10	40	56	112	11	28	25	0.53								
	6	237	74	9	8	-	-	7	193	30	20	50	55	129	16	37	0.9									
	8	250	82	12	8	-	-	9	193	30	20	55	55	144	20	42	2.1									

8* is used in common with 8-45.
No. 6060, 8080 and 9090 are applicable to HFS6-6060, HFS8-8080 and HFS8-9090.
No. 5 and 6 apply to extrusions with 6-slot width 20 Square Type and 8-slot width 30 Square Types. No. 8 apply to extrusions 10-slot width 40 and 45 Square Type.
No. 5040 is applicable to the extrusion HFS5-4040. No. 5050 is applicable to the extrusion HFS6-5050.

Ordering Example
Part Number
HAJP5

Days to Ship
Configure Online

Example
See left-hand page.