

Stepped Detachable Hinges / Vertical Detachable Hinges / Weld-On Detachable Hinges

Weld-On Hinges / Long Hinges


Stepped Detachable Hinges **RoHS**

HHSPDL (Left Door Type)
HHSPDR (Right Door Type)

(Left Door Type)

Part Number Type	T	T ₁	*Allowable Load (kg)	Weight (g)	Unit Price 1~19 pc(s).	Volume Discount Rate 20~
HHSPDL	3	10	7	40		
HHSPDR	5	12		42		

*The allowable load is the value when 2 pieces are used.

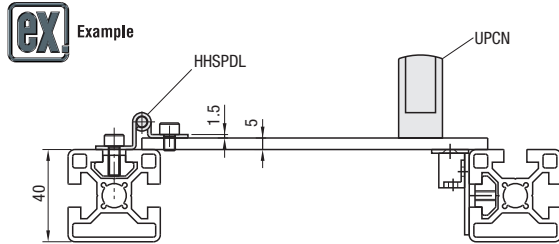

*Example is the view from the top.

Vertical Detachable Hinges **RoHS**

HHSV

Material: 304 Stainless Steel, Surface Treatment: Gloss Tumble Polish

Part Number Type	L	N Through Countersink	*Allowable Load (kg)	Mass (g)	Unit Price 1~9 pc(s).	Volume Discount Rate 10~
HHSV	35		2	13		
	51	3.2	6.2	4	30	
	60			6	45	
	80	4.2	8.2	10	95	

L	W	P	D	H	t	R	R ₁
35	8	27	3	6	2	9	8
51	11	40	4	8	2.5	15	14.4
60	13	48	5	9.5	3	18	18
80	14.5	68	6	11.5	4.5	27	27

*The allowable load is the value when 2 pieces are used.

Ordering Example
Part Number
HHSPDL3
HHSV51

Days to Ship [Configure Online](#)

Weld-On Detachable Hinges **RoHS**

HHSM L (For Left-hand Use)
HHSM R (For Right-hand Use)

Material: Low Carbon Steel, Surface Treatment: Trivalent Chromate

Part Number Type	L	W	T (R)	*Allowable Load (kg)	Weight (g)	Unit Price 1~19 pc(s).	Volume Discount Rate 20~
HHSM L (For Left-hand Use)	50	32	1.6	7.5	7	30	
HHSM R (For Right-hand Use)	64	36	1.6	7.5	10	45	
	75	38	2	8.5	15	65	

*The allowable load is the value when 2 pieces are used.

Weld-On Detachable Hinges for Heavy Loads **RoHS**

HHSMZ L (For Left-hand Use)
HHSMZ R (For Right-hand Use)
HHSMY L (For Left-hand Use)
HHSMY R (For Right-hand Use)

Type	Material	Surface Treatment
HHSMZ L	Low Carbon Steel	Trivalent Chromate
HHSMZ R	304 Stainless Steel	Mirror Polishing
HHSMY L	Low Carbon Steel	Trivalent Chromate
HHSMY R	304 Stainless Steel	Mirror Polishing

Material: Low Carbon Steel or 304 Stainless Steel, Surface Treatment: Trivalent Chromate or Mirror Polishing

Part Number Type	L	W	T (R)	D	*Allowable Load (kg)	Weight (g)	Unit Price 1~19 pc(s).	Volume Discount Rate 20~
HHSMZ L (For Left-hand Use)	50	40	2.6	10.5	5	15	62	
HHSMZ R (For Right-hand Use)	65	50	2.6	10.5	5	20	95	
HHSMY L (For Left-hand Use)	75	70	3.2	12.5	6	30	180	
HHSMY R (For Right-hand Use)	100	82	4	16	8	50	335	
HHSMY L (For Left-hand Use)	50	40	2.5	10.5	5	15	60	
HHSMY R (For Right-hand Use)	65	50	2.5	10.5	5	20	89	
HHSMY L (For Left-hand Use)	75	70	3	12	6	30	165	
HHSMY R (For Right-hand Use)	100	82	4	16	8	50	347	

*The allowable load is the value when 2 pieces are used.

Ordering Example
Part Number
HHSM L50
HHSMY R75

Days to Ship [Configure Online](#)

Weld-On Stainless Steel Hinges **RoHS**

HHSY

Material: 304 Stainless Steel, Surface Treatment: Buffered Surface

Part Number Type	L	W	C	C ₁	t	*Allowable Load (kg)	Weight (g)	Unit Price 1~19 pc(s).	Volume Discount Rate 20~
HHSY	40	35	3	6.3	1.5	6	25		
	50	30	3	6.4	1.5	8	30		
	65					13	66		
	75	50	4	8.5	2	15	76		
	90					25	190		
100	60	6	12.7	3	30	200			

*The allowable load is the value when 2 pieces are used.

Weld-On Steelz Hinges **RoHS**

HHSYT

Material: Low Carbon Steel, Surface Treatment: Trivalent Chromate

Part Number Type	L	W	*Allowable Load (kg)	Division	Weight (g)	Unit Price 1~19 pc(s).	Volume Discount Rate 20~
HHSYT	60	50	25	3	105		
	90	60	40	5	180		
	100	80	45	5	245		

*The allowable load is the value when 2 pieces are used.

Weld-On Hinges for Heavy Loads **RoHS**

HHSYZ

Material: 304 Stainless Steel, Surface Treatment: Brushed Finish

Part Number Type	L	W	(D)	t	Shape No.	*Allowable Load (kg)	Weight (g)	Unit Price 1~19 pc(s).	Volume Discount Rate 20~
HHSYZ	50	50	12	3	A	20	90		
	60	64				25	130		
	75	70				30	165		
	100	100	20	4	B	60	520		
	125	100				70	610		
	150	120				90	840		

*The allowable load is the value when 2 pieces are used.

Long Hinges **RoHS**

HHSLV

Material: 304 Stainless Steel

Long hinges can be cut for use.

Part Number Type	L	Mass (g)	Unit Price 1~9 pc(s).	Volume Discount Rate 10~
HHSLV	300	165		
	350	190		
	450	250		
	600	335		
	750	410		
	850	470		
1000	580			

Ordering Example
Part Number
HHSY50
HHSYT90
HHSYZ100
HHSLV300

Days to Ship [Configure Online](#)