


Hexagon Socket Set Screws


Flat Point (Box)

Screws / Washers / Nuts

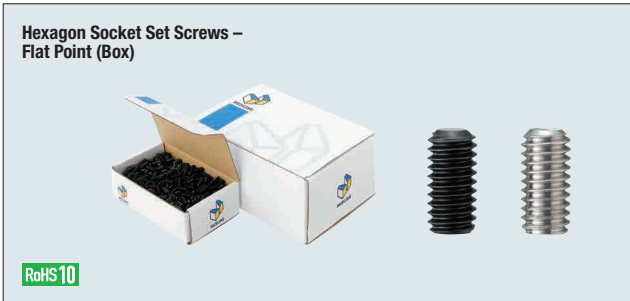

RoHS 10

Type	Material	Hardness	Surface Treatment
BOX-MSSF	4137 Alloy Steel	45 HRC min.	Black Oxide
BOX-MSSF5	304 Stainless Steel or Equivalent	—	—

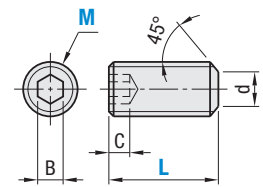

M x P (Coarse)	B	C (Min.)	d (Max.)
2 x 0.4	0.9	0.8	1
2.5 x 0.45	1.3	1.2	1.5
2.6 x 0.45	1.3	1.2	1.5
3 x 0.5	1.5	1.2	2
4 x 0.7	2	1.5	2.5
5 x 0.8	2.5	2	3.5
6 x 1.0	3	2	4
8 x 1.25	4	3	5

ⓘ Can be ordered as single item. P.2409
 ⓘ When you order, please specify the box quantity. Minimum order is 1 box.

Part Number Example
 Part Number
 BOX-MSSF3-10
 BOX-MSSF52.5-5


Part Number		Pcs./Box						
Type	M - L							
BOX-MSSF	2 - 2	1,000						
	3							
	4							
	5							
	6							
	2.5 - 3		500					
	4							
	5							
	6							
	2.6 - 3			1,000				
	4							
	5							
	6							
	3 - 3				500			
	4							
	5							
	6							
	8							
	10							
	4 - 4					1,000		
	5							
	6							
	8							
	10							
	5 - 5						500	
	6							
	8							
	10							
	6 - 5							200
	6							
8								
10								
12								
15								
16								
20								
25								
8 - 6	500							
8								
10								
12								
15								
16								
20								
25								
30								

Part Number		Pcs./Box					
Type	M - L						
BOX-MSSF5 Stainless Steel	2 - 2	1,000					
	3						
	4						
	5						
	6						
	2.5 - 3		1,000				
	4						
	5						
	6						
	2.6 - 3			1,000			
	4						
	5						
	6						
	3 - 3				1,000		
	4						
	5						
	6						
	8						
	10						
	4 - 4					1,000	
	5						
	6						
	8						
	10						
	5 - 5						1,000
	6						
	8						
	10						

Hexagon Socket Set Screws


Cup Point (Box)

Screws / Washers / Nuts

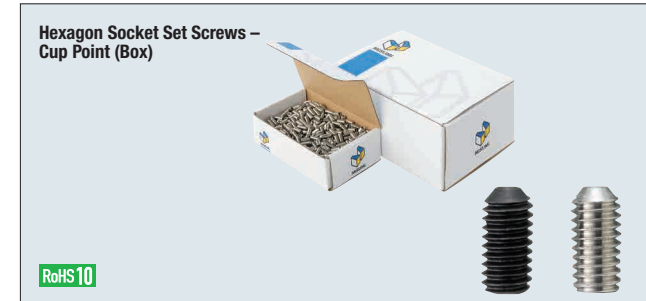

RoHS 10

Type	Material	Hardness	Surface Treatment
BOX-MSSK	4137 Alloy Steel	45 HRC min.	Black Oxide
BOX-MSSU	304 Stainless Steel	—	—

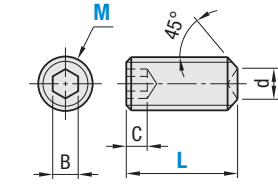

M x P (Coarse)	B	C (Min.)	d (Max.)
2 x 0.4	0.9	0.8	1
2.5 x 0.45	1.3	1.2	1.2
2.6 x 0.45	1.3	1.2	1.2
3 x 0.5	1.5	1.2	1.4
4 x 0.7	2	1.5	2
5 x 0.8	2.5	2	2.5
6 x 1	3	2	3
8 x 1.25	4	3	5
10 x 1.5	5	4	6
12 x 1.75	6	4.8	8

ⓘ Can be ordered as single item. P.2409
 ⓘ When you order, please specify the box quantity. Minimum order is 1 box.

Part Number Example
 Part Number
 BOX-MSSK5-5
 BOX-MSSU2-3

Part Number		Pcs./Box						
Type	M - L							
BOX-MSSK	2 - 2	1,000						
	3							
	4							
	5							
	6							
	2.5 - 3		500					
	4							
	5							
	6							
	2.6 - 3			1,000				
	4							
	5							
	6							
	3 - 3				500			
	4							
	5							
	6							
	8							
	10							
	4 - 4					1,000		
	5							
	6							
	8							
	10							
	5 - 5						500	
	6							
	8							
	10							
	6 - 5							400
	6							
8								
10								
12								
15								
16								
20								
25								
8 - 6	200							
8								
10								
12								
15								
16								
20								
25								
30								
10 - 12		500						
10								
15								
20								
25								
30								
12 - 15			200					
12								
15								
20								
25								
30								

Part Number		Pcs./Box					
Type	M - L						
BOX-MSSU Stainless Steel	2 - 2	1,000					
	3						
	4						
	5						
	6						
	2.5 - 3		1,000				
	4						
	5						
	6						
	2.6 - 3			1,000			
	4						
	5						
	6						
	3 - 3				1,000		
	4						
	5						
	6						
	8						
	10						
	4 - 4					1,000	
	5						
	6						
	8						
	10						
	5 - 5						1,000
	6						
	8						
	10						